


Technical data sheet

Strain relief on three sides, empty housing, internal height 115 mm
Item number: 7215760

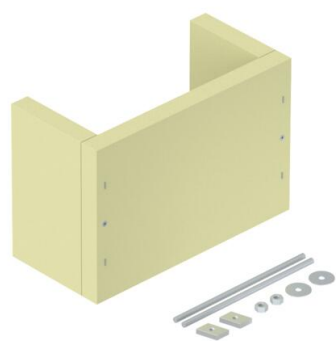

Strain relief as an effective support measure for vertical cable routing, according to DIN 4102 Part 12. Approved for all cable types and all vertical routing systems, which are mounted directly on solid walls. Maintenance of electrical function classes E30 to E90. Empty housing for individual filling with the PYROSIT® NG fire protection foam and/or PYROPLUG® Block insulation systems, incl. mounting set and labelling panel.



Calcium silicate

Master data		
Item number	7215760	
Description 1	Strain relief	
Description 2	for vertical cable routing	
Manufacturer	OBO	
Dimension	300x140x200	
Colour	Cream; RAL 9001	
Material	Calcium silicate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	320 kg	
Weight unit	kg/100 pc.	

Technical data sheet

Strain relief on three sides, empty housing, internal height
115 mm

Item number: 7215760



Dimensions		
	Length	200 mm
	Width	300 mm
	Height	140 mm
	Dimension B	300 mm
	Dimension b	250 mm
	Dimension H	200 mm
	Dimension t	140 mm
	Dimension t	115 mm

Technical data		
	Shape	Rectangular
	Accessories required	no