


# Technical data sheet

Strain relief on three sides, with mineral wool, internal height 115 mm  
Item number: 7215706

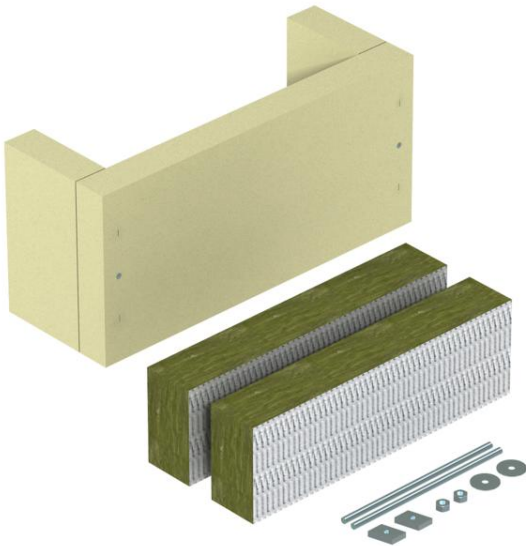

Strain relief as an effective support measure for vertical cable routing, according to DIN 4102 Part 12, approved for all cable types and all vertical routing systems. Maintenance of electrical function classes E30 to E90. Housing including mineral fibre panels, fastening material, ASX fire protection coating in cartridge and identification plate.

Calcium silicate

Master data		
Item number	7215706	
Description 1	Strain relief	
Description 2	for vertical cable routing	
Manufacturer	OBO	
Dimension	440x160x140	
Colour	Cream; RAL 9001	
Material	Calcium silicate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	466 kg	
Weight unit	kg/100 pc.	

# Technical data sheet

Strain relief on three sides, with mineral wool, internal height 115 mm  
Item number: 7215706



Dimensions		
	Length	140 mm
	Width	440 mm
	Height	160 mm
	Dimension B	440 mm
	Dimension b	350 mm
	Dimension H	140 mm
	Dimension t	160 mm
	Dimension t	115 mm

Technical data		
	Fire protection version	Soft insulation
	Shape	Rectangular
	Accessories required	no