


# Technical data sheet

Strain relief on four sides, empty housing, internal height  
175 mm

Item number: 7215784



Strain relief as an effective support measure for vertical cable routing, according to DIN 4102 Part 12. Approved for all cable types and vertical ladders, created as suspended mounting. Maintenance of electrical function classes E30 to E90. Empty housing for individual filling with the PYROSIT® NG fire protection foam and/or PYROPLUG® Block insulation systems, incl. mounting set and labelling panel.

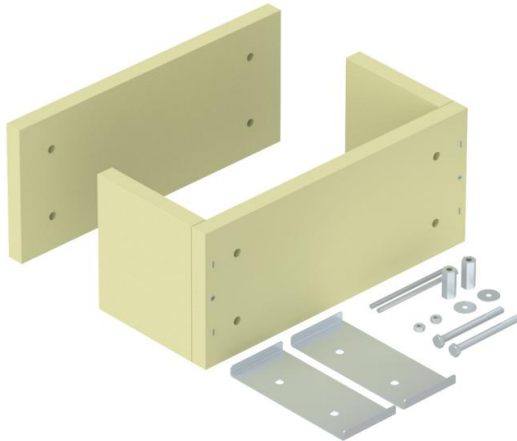

Calcium silicate

## Master data

|                     |                            |
|---------------------|----------------------------|
| Item number         | 7215784                    |
| Description 1       | Strain relief              |
| Description 2       | for vertical cable routing |
| Manufacturer        | OBO                        |
| Dimension           | 460x225x200                |
| Colour              | Cream; RAL 9001            |
| Material            | Calcium silicate           |
| Smallest sales unit | 1                          |
| Unit of quantity    | Piece                      |
| Weight              | 785 kg                     |
| Weight unit         | kg/100 pc.                 |

# Technical data sheet

Strain relief on four sides, empty housing, internal height  
175 mm

Item number: 7215784



| Dimensions |             |        |
|------------|-------------|--------|
|            | Length      | 200 mm |
|            | Width       | 460 mm |
|            | Height      | 225 mm |
|            | Dimension B | 460 mm |
|            | Dimension b | 410 mm |
|            | Dimension H | 200 mm |
|            | Dimension t | 225 mm |
|            | Dimension t | 175 mm |

| Technical data |             |
|----------------|-------------|
| Shape          | Rectangular |