


Technical data sheet

Strain relief on three sides, with mineral wool, internal height 115 mm

Item number: 7215709

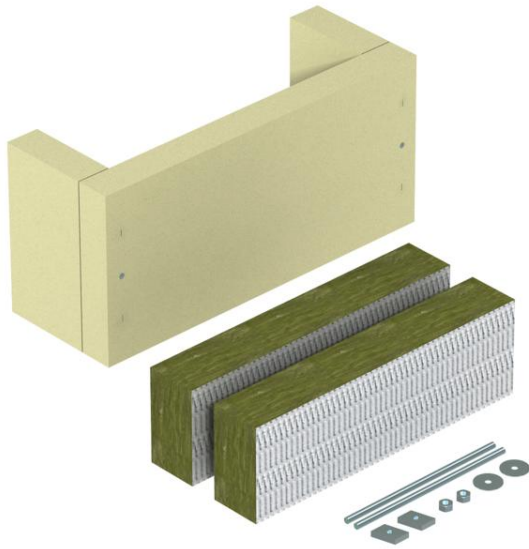

Strain relief as an effective support measure for vertical cable routing, according to DIN 4102 Part 12, approved for all cable types and all vertical routing systems. Maintenance of electrical function classes E30 to E90. Housing including mineral fibre panels, fastening material, ASX fire protection coating in cartridge and identification plate.

Calcium silicate

Master data

Item number	7215709
Description 1	Strain relief
Description 2	for vertical cable routing
Manufacturer	OBO
Dimension	540x160x140
Colour	Cream; RAL 9001
Material	Calcium silicate
Smallest sales unit	1
Unit of quantity	Piece
Weight	506 kg
Weight unit	kg/100 pc.

Technical data sheet

Strain relief on three sides, with mineral wool, internal height 115 mm
Item number: 7215709



Dimensions		
	Length	140 mm
	Width	540 mm
	Height	160 mm
	Dimension B	540 mm
	Dimension b	450 mm
	Dimension H	140 mm
	Dimension t	160 mm
	Dimension t	115 mm

Technical data		
	Fire protection version	Soft insulation
	Shape	Rectangular
	Accessories required	no