


# Technical data sheet

Strain relief on three sides, with mineral wool, internal height 175 mm

Item number: 7215719

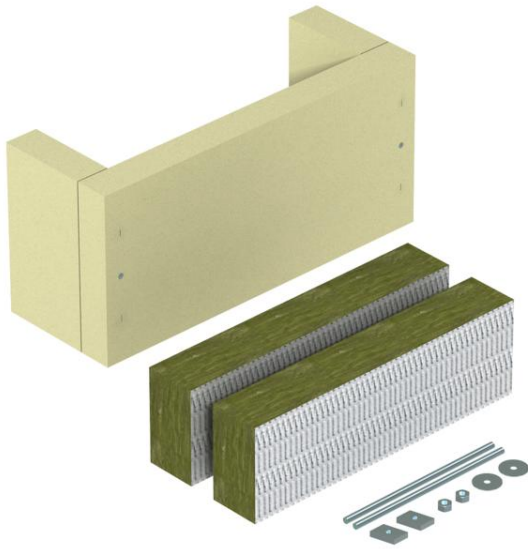

Strain relief as an effective support measure for vertical cable routing, according to DIN 4102 Part 12, approved for all cable types and all vertical routing systems. Maintenance of electrical function classes E30 to E90. Housing including mineral fibre panels, fastening material, ASX fire protection coating in cartridge and identification plate.

Calcium silicate

## Master data

Item number	7215719
Description 1	Strain relief
Description 2	for vertical cable routing
Manufacturer	OBO
Dimension	540x220x160
Colour	Cream; RAL 9001
Material	Calcium silicate
Smallest sales unit	1
Unit of quantity	Piece
Weight	700 kg
Weight unit	kg/100 pc.

# Technical data sheet

Strain relief on three sides, with mineral wool, internal height 175 mm  
Item number: 7215719



Dimensions		
	Length	160 mm
	Width	540 mm
	Height	220 mm
	Dimension B	540 mm
	Dimension b	450 mm
	Dimension H	160 mm
	Dimension t	220 mm
	Dimension t	175 mm

Technical data		
Fire protection version	Soft insulation	
Shape	Rectangular	
Accessories required	no	