


# Technical data sheet

Strain relief on three sides, empty housing, internal height  
175 mm

Item number: 7215770



Strain relief as an effective support measure for vertical cable routing, according to DIN 4102 Part 12. Approved for all cable types and all vertical routing systems, which are mounted directly on solid walls. Maintenance of electrical function classes E30 to E90. Empty housing for individual filling with the PYROSIT® NG fire protection foam and/or PYROPLUG® Block insulation systems, incl. mounting set and labelling panel.

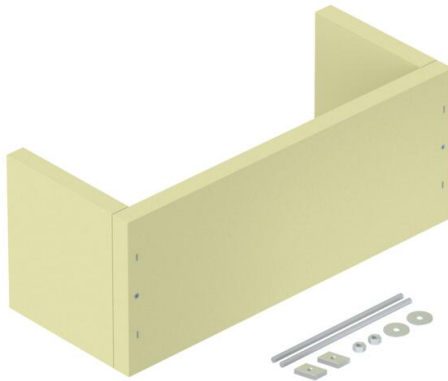

Calcium silicate

## Master data


Item number	7215770
Description 1	Strain relief
Description 2	for vertical cable routing
Manufacturer	OBO
Dimension	500x200x200
Colour	Cream; RAL 9001
Material	Calcium silicate
Smallest sales unit	1
Unit of quantity	Piece
Weight	475 kg
Weight unit	kg/100 pc.

# Technical data sheet

Strain relief on three sides, empty housing, internal height 175 mm

Item number: 7215770

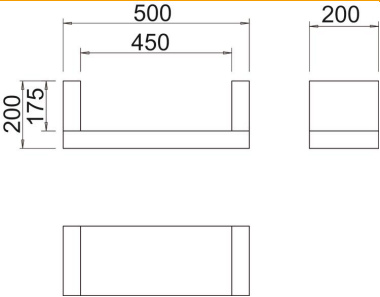

Dimensions		
	Length	200 mm
	Width	500 mm
	Height	200 mm
	Dimension B	500 mm
	Dimension b	450 mm
	Dimension H	200 mm
	Dimension t	200 mm
	Dimension t	175 mm

Technical data		
	Shape	Rectangular