

Technical data sheet

VA roof conductor holder, sloping roof

Item number: 5408074



- For routing of the isCon® conductor on pitched roofs
- Cable bracket with sprung discs to protect the screws against loosening



A2 Stainless steel

Master data

Item number	5408074
Description 1	Roof conductor holder
Description 2	for tiled roofs
Manufacturer	OBO
Dimension	280mm
Material	Stainless steel
Smallest sales unit	25
Unit of quantity	Piece
Weight	16.9 kg
Weight unit	kg/100 pc.


Technical data sheet

VA roof conductor holder, sloping roof

Item number: 5408074



Dimensions

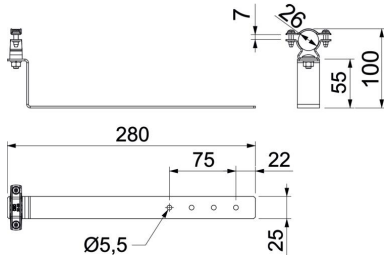

Length	280 mm
Dimension L	7 mm

Technical data

Connection	Round conductor
Application	Pitched roof
Conductor fastening type	With clamp clip
Conductor diameter, min.	26
Mounting type	Screw-on
Mounting height	55 mm
Material of the holder	Rustproof steel (V2A)
Material of the support	Rustproof steel (V2A)