

Technical data sheet

VA cable bracket with tightening strap

Item number: 5408068



Cable bracket with tightening strap for isCon® conductor, for mounting on pipes with $\varnothing \leq 600$ mm. Including sprung discs to protect the screws against loosening.



A2 Stainless steel

Master data

Item number	5408068
Type	isCon HS 26 VA
Description 1	Cable bracket with tight.strap
Description 2	for isCon conductor, grey
Manufacturer	OBO
Dimension	Ø26mm
Colour	Light grey
Material	Stainless steel
Smallest sales unit	10
Unit of quantity	Piece
Weight	25.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,3201 kg CO2e / 1 Piece


Technical data sheet

VA cable bracket with tightening strap

Item number: 5408068



Dimensions

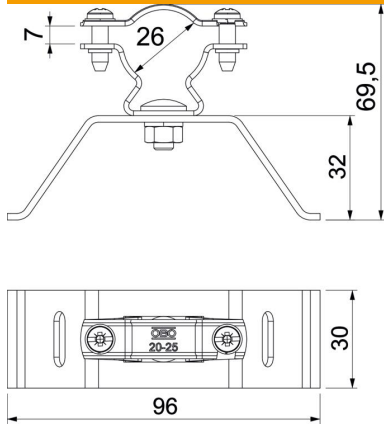

Dimension d min.	26 mm
Dimension H	69.5 mm
Dimension L	7 mm

Technical data

Material of the base	Stainless steel, rustproof 1.4301
Material of the crossbar	Stainless steel, rustproof 1.4301
Material upper part	V2A
Material lower part	V2A