

Technical data sheet

Insulated air-termination rod

Item number: 5408942



- For isolated creation of air-termination systems
- Suitable for isFang air-termination rod stand, type isFang 3B-100/150
- Suitable for wind loads according to Eurocode 1: DIN EN 1991-1-4
- For installation on the building structure with isFang support
- Fastening of the OBO isCon® conductor possible using accessories
- Suitable for externally routed isCon® conductors
- Stainless steel standpipe (V2A)
- Centre section made of fibre-glass reinforced plastic (GRP)
- Aluminium air-termination tip



GFK Fibre-glass-reinforced plastic

Master data

Item number	5408942
Type	isFang 4000
Description 1	Insulated interception rod
Manufacturer	OBO
Dimension	4000mm
Colour	Light grey
Material	Fibre-glass-reinforced plastic
Smallest sales unit	1
Unit of quantity	Piece
Weight	680 kg
Weight unit	kg/100 pc.


Technical data sheet

Insulated air-termination rod

Item number: 5408942



Dimensions

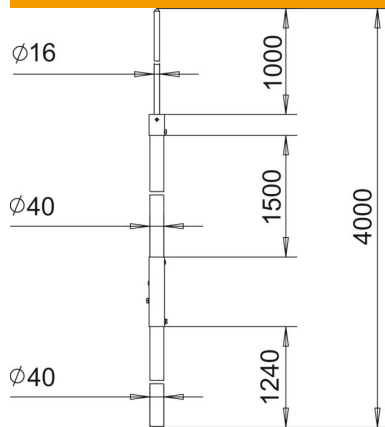

Length	4,000 mm
Dimension A	1,240 mm
Dimension B	1,000 mm
Dimension d min.	40 mm
Dimension H	1,500 mm

Technical data

Connection	Round conductor
Version for	Air-termination rod
High voltage-resistant, insulated version	yes