

# Technical data sheet

isFang, insulated air-termination rod for inner-routed is-Con® conductor Professional Plus

Item number: 5408936



- For installation of the OBO isCon® Pro+ conductor in the pipe
- For mounting on the building structure with isFang support
- Suitable for wind loads according to Eurocode 1: DIN EN 1991-1-4
- Inclusive connection element (type isCon IN connect)
- Inclusive potential connection (type isCon In PAE)
- Aluminium standpipe and air-termination tip
- Centre section made of fibre-glass reinforced plastic (GRP)



**GFK** Fibre-glass-reinforced plastic

## Master data

Item number	5408936
Type	isFang IN 6000
Description 1	Insulated interception rod
Description 2	for isCon conductor, internal
Manufacturer	OBO
Dimension	6000mm
Material	Fibre-glass-reinforced plastic
Smallest sales unit	1
Unit of quantity	Piece
Weight	835 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	80,1525 kg CO2e / 1 Piece


# Technical data sheet

isFang, insulated air-termination rod for inner-routed is-Con® conductor Professional Plus

Item number: 5408936



## Dimensions

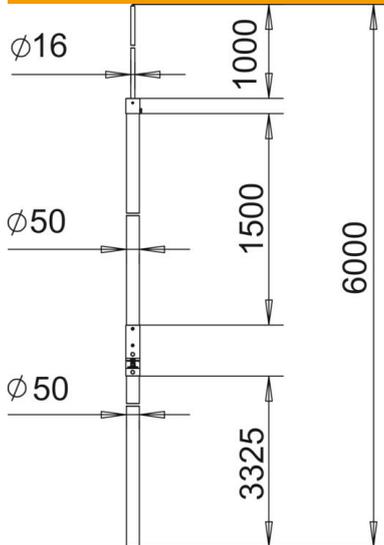

Length	6,000 mm
Dimension A	3,325 mm
Dimension B	1,000 mm
Dimension d min.	50 mm
Dimension H	1,500 mm
Dimension L	6,000 mm

## Technical data

Connection	Round conductor
Version for High voltage-resistant, insulated version	Air-termination rod yes