

# Technical data sheet

## Fastening clip 604, light duty

Item number: 1003194



Single-lobe fastening clip for cables and pipes.  
\* Sizes 3 and 4 are not suitable for nail device  
\* Sizes 3 to 21 are not suitable for bolt-firing tool



|    |                   |
|----|-------------------|
| St | Steel             |
| G  | Electrogalvanised |

### Master data

|                                    |                            |
|------------------------------------|----------------------------|
| Item number                        | 1003194                    |
| Type                               | 604 19 G                   |
| Description 1                      | Fastening clip             |
| Description 2                      | single lobe                |
| Manufacturer                       | OBO                        |
| Dimension                          | 19mm                       |
| Material                           | Steel                      |
| Surface                            | Electrogalvanised          |
| Surface standard                   | EN ISO 19598 / EN ISO 4042 |
| Smallest sales unit                | 100                        |
| Unit of quantity                   | Piece                      |
| Weight                             | 0.411 kg                   |
| Weight unit                        | kg/100 pc.                 |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0104 kg CO2e / 1 Piece   |


# Technical data sheet

## Fastening clip 604, light duty

Item number: 1003194



### Dimensions

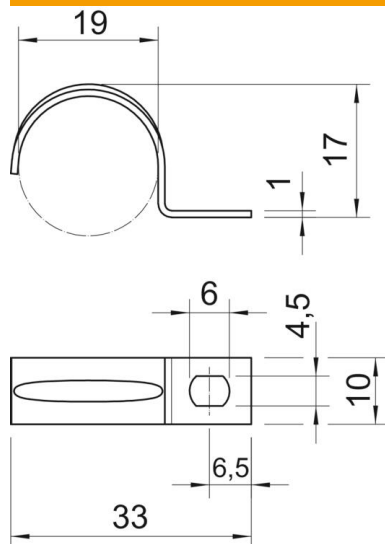

|             |        |
|-------------|--------|
| Length      | 33 mm  |
| Width       | 10 mm  |
| Height      | 17 mm  |
| Dimension A | 6.5 mm |
| Dimension b | 10 mm  |
| Dimension D | 19 mm  |
| Dimension d | 4.5 mm |
| Dimension e | 6 mm   |
| Dimension H | 17 mm  |
| Dimension L | 33 mm  |
| Dimension t | 1 mm   |

### Technical data

|                                  |             |
|----------------------------------|-------------|
| Distance to the wall             | no          |
| Number of cables/pipes           | 1           |
| Version for                      | Single-lobe |
| Fastening type                   | Screw hole  |
| For diameter                     | 19          |
| Suitable in fire protection area | no          |
| Halogen-free                     | yes         |
| Plastic-covered                  | no          |
| Hole size                        | 4,5 x 6     |
| Material thickness               | 1 mm        |
| Nominal diameter                 | 19 mm       |
| UV-resistant                     | yes         |