

Technical data sheet

Fastening clip 1015, medium-duty

Item number: 1009168



Single-lobe fastening clip for cables and pipes.



St	Steel
G	Electrogalvanised

Master data

Item number	1009168
Type	1015 14 G
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	14mm
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.71 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0147 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 1015, medium-duty

Item number: 1009168



Dimensions

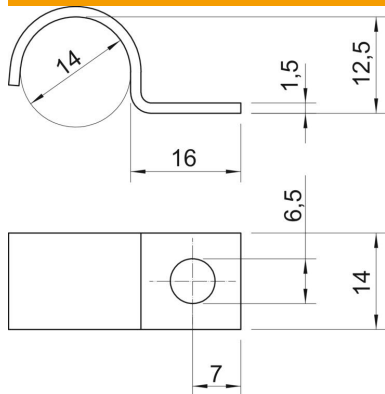

Length	16 mm
Width	14 mm
Height	12.5 mm
Dimension A	7 mm
Dimension b	14 mm
Dimension D	14 mm
Dimension H	12.5 mm
Dimension L	16 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
Maintain electrical functions	yes
For diameter	14
Suitable in fire protection area	yes
Halogen-free	yes
Plastic-covered	no
Hole size	6,5
Material thickness	1.5 mm
Nominal diameter	14 mm
UV-resistant	yes