


# Technical data sheet

## Fastening clip 1015, medium-duty

Item number: 1009362

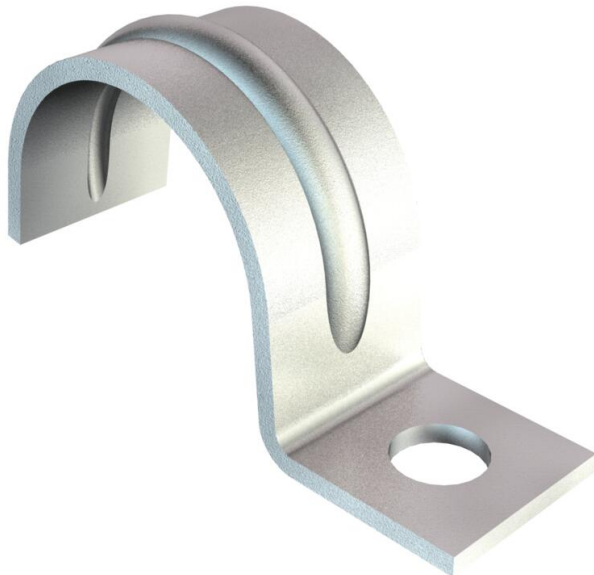

Single-lobe fastening clip for cables and pipes.  
Beading from size 20.



|    |                   |
|----|-------------------|
| St | Steel             |
| G  | Electrogalvanised |

### Master data

|                                    |                            |
|------------------------------------|----------------------------|
| Item number                        | 1009362                    |
| Type                               | 1015 28 G                  |
| Description 1                      | Fastening clip             |
| Description 2                      | single lobe                |
| Manufacturer                       | OBO                        |
| Dimension                          | 28mm                       |
| Material                           | Steel                      |
| Surface                            | Electrogalvanised          |
| Surface standard                   | EN ISO 19598 / EN ISO 4042 |
| Smallest sales unit                | 100                        |
| Unit of quantity                   | Piece                      |
| Weight                             | 1.25 kg                    |
| Weight unit                        | kg/100 pc.                 |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0242 kg CO2e / 1 Piece   |


# Technical data sheet

## Fastening clip 1015, medium-duty

Item number: 1009362



### Dimensions

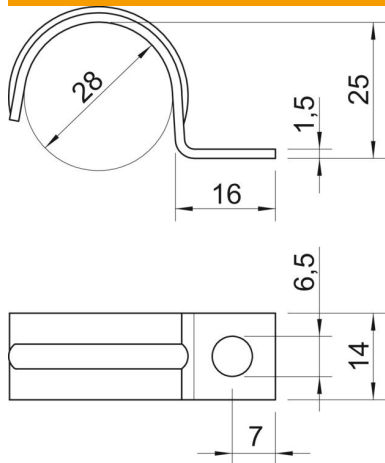

|             |       |
|-------------|-------|
| Length      | 16 mm |
| Width       | 14 mm |
| Height      | 25 mm |
| Dimension A | 7 mm  |
| Dimension b | 14 mm |
| Dimension D | 28 mm |
| Dimension H | 25 mm |
| Dimension L | 16 mm |

### Technical data

|                                  |             |
|----------------------------------|-------------|
| Distance to the wall             | no          |
| Number of cables/pipes           | 1           |
| Version for                      | Single-lobe |
| Fastening type                   | Screw hole  |
| Maintain electrical functions    | yes         |
| For diameter                     | 28          |
| Suitable in fire protection area | no          |
| Halogen-free                     | yes         |
| Plastic-covered                  | no          |
| Hole size                        | 6,5         |
| Material thickness               | 1.5 mm      |
| Nominal diameter                 | 28 mm       |
| UV-resistant                     | yes         |