

Technical data sheet

1015 D fastening clip

Item number: 1009465



Fastening clip with a central fastening point for 2 cables or 2 pipes



St	Steel
G	Electrogalvanised

Master data

Item number	1009465
Type	1015 D 10 G
Description 1	Fastening clip
Description 2	for 2 cables
Manufacturer	OBO
Dimension	10mm
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.3 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0113 kg CO2e / 1 Piece


Technical data sheet

1015 D fastening clip

Item number: 1009465



Dimensions

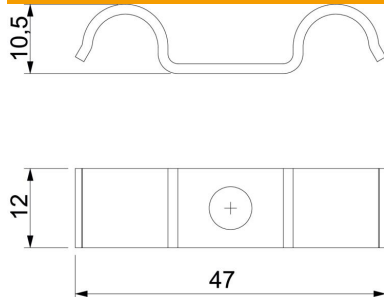

Length	47 mm
Width	12 mm
Height	10.5 mm
Dimension A	47 mm
Dimension b	12 mm
Dimension H	10.5 mm

Technical data

Distance to the wall	no
Number of cables/pipes	2
Version for	Single-lobe
Fastening type	Screw hole
Maintain electrical functions	yes
For diameter	10
Suitable in fire protection area	yes
Halogen-free	yes
Plastic-covered	no
Hole size	6,5
Material thickness	1.5 mm
Nominal diameter	10 mm
Clamping range D, min.	10 mm
UV-resistant	yes