

Technical data sheet

Fastening clip 1015 D

Item number: 1009477



Fastening clip with a central fastening point for 2 cables or 2 pipes



St	Steel
G	Electrogalvanised

Master data

Item number	1009477
Type	1015 D 16 G
Description 1	Fastening clip
Description 2	for 2 cables
Manufacturer	OBO
Dimension	16mm
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.414 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0177 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 1015 D

Item number: 1009477



Dimensions

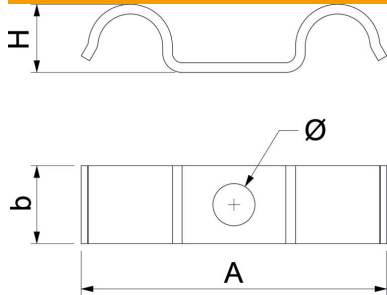

Length	60 mm
Width	14 mm
Height	16 mm
Dimension A	60 mm
Dimension b	14 mm
Dimension H	16 mm

Technical data

Distance to the wall	no
Number of cables/pipes	2
Version for	Single-lobe
Fastening type	Screw hole
Maintain electrical functions	yes
For diameter	16
Suitable in fire protection area	yes
Halogen-free	yes
Plastic-covered	no
Hole size	6,5
Material thickness	1.5 mm
Nominal diameter	16 mm
Clamping range D, min.	16 mm
UV-resistant	yes