

# Technical data sheet

## Fastening clip 1015, for direct fastening

Item number: 1009512



Single-lobe fastening clip for cables and pipes.



|           |                   |
|-----------|-------------------|
| <b>St</b> | Steel             |
| <b>G</b>  | Electrogalvanised |

### Master data

|                                    |                            |
|------------------------------------|----------------------------|
| Item number                        | 1009512                    |
| Type                               | 1015 12 OL G               |
| Description 1                      | Fastening clip             |
| Description 2                      | one-lobed, without hole    |
| Manufacturer                       | OBO                        |
| Dimension                          | 12mm                       |
| Material                           | Steel                      |
| Surface                            | Electrogalvanised          |
| Surface standard                   | EN ISO 19598 / EN ISO 4042 |
| Smallest sales unit                | 100                        |
| Unit of quantity                   | Piece                      |
| Weight                             | 0.667 kg                   |
| Weight unit                        | kg/100 pc.                 |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0124 kg CO2e / 1 Piece   |


# Technical data sheet

## Fastening clip 1015, for direct fastening

Item number: 1009512



### Dimensions

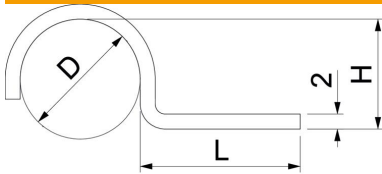

|             |         |
|-------------|---------|
| Length      | 29.5 mm |
| Width       | 14 mm   |
| Height      | 12.5 mm |
| Dimension B | 14 mm   |
| Dimension H | 11 mm   |
| Dimension L | 16 mm   |



### Technical data

|                                  |               |
|----------------------------------|---------------|
| Distance to the wall             | no            |
| Number of cables/pipes           | 1             |
| Version for                      | Single-lobe   |
| Fastening type                   | Miscellaneous |
| Maintain electrical functions    | yes           |
| For diameter                     | 12            |
| Suitable in fire protection area | yes           |
| Halogen-free                     | yes           |
| Plastic-covered                  | no            |
| Material thickness               | 1.5 mm        |
| UV-resistant                     | yes           |