

Technical data sheet

Fastening clip 1015 RB

Item number: 1010794



For fastening of rigid and bending plastic pipes on concrete substrates using knock-in anchors 903/RB and flatteners with hand protection 915/RB.



St Steel

G Electrogalvanised

Master data

Item number	1010794
Type	1015 RB 20 G
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	20mm
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.1 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,018 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 1015 RB

Item number: 1010794



Dimensions

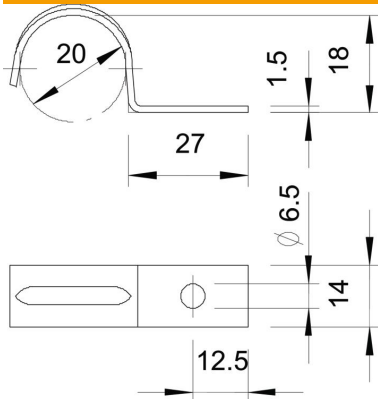

Dimension D	20 mm
Dimension H	18 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	20
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	6,5
Material thickness	1.5 mm
Nominal diameter	20 mm
ROHS-conformant	yes
UV-resistant	yes