

Technical data sheet

Fastening clip 822, heavy-duty, A4

Item number: 1013865



Single-lobe fastening clip for cables and pipes.



A4	Stainless steel
2B	Bright, treated

Master data

Item number	1013865
Type	822 10 A4
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	10mm
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.075 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0679 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 822, heavy-duty, A4

Item number: 1013865



Dimensions

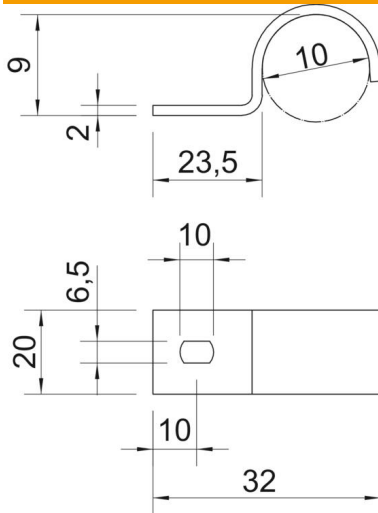

Length	36 mm
Width	20 mm
Height	9 mm
Dimension A	10 mm
Dimension b	20 mm
Dimension D	10 mm
Dimension H	9 mm
Dimension L	23.5 mm
Dimension L1	36 mm
Dimension t	2 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	10
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10
Material thickness	2 mm
Nominal diameter	10 mm
UV-resistant	yes