

Technical data sheet

Fastening clip 822, heavy duty, A4

Item number: 1013893



Fastening clip, single-lobe, 25 mm



A4 Stainless steel

2B Bright, treated

Master data

Item number	1013893
Type	822 25 A4
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	25mm
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	2.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,179 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 822, heavy duty, A4

Item number: 1013893



Dimensions

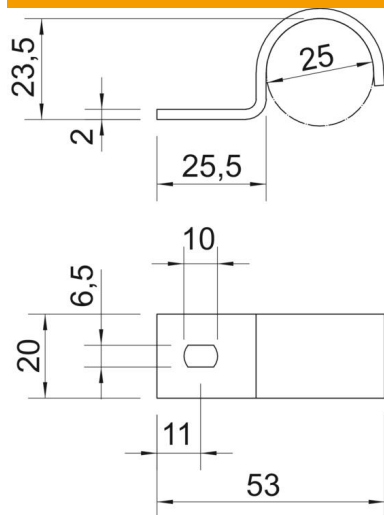

Length	53 mm
Width	20 mm
Height	23.5 mm
Dimension A	11 mm
Dimension b	20 mm
Dimension D	25 mm
Dimension H	23.5 mm
Dimension L	25.5 mm
Dimension L1	53 mm
Dimension t	2 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	25
Suitable in fire protection area	no
Size	M25
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10
Material thickness	2 mm
Nominal diameter	25 mm
UV-resistant	yes