

Technical data sheet

Fastening clip 822, heavy duty, A4

Item number: 1013921



Fastening clip, single-lobe, 50 mm



A4 Stainless steel

2B Bright, treated

Master data

Item number	1013921
Type	822 50 A4
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	50mm
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	7.69 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4313 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 822, heavy duty, A4

Item number: 1013921



Dimensions

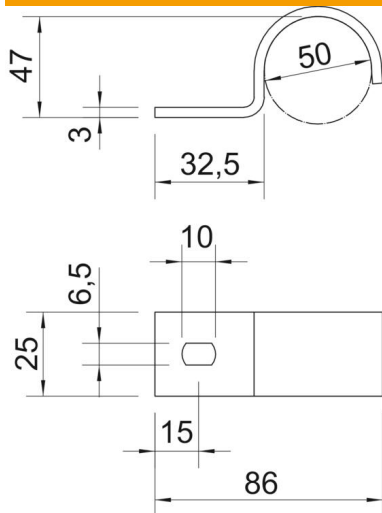

Length	86 mm
Width	25 mm
Height	47 mm
Dimension A	15 mm
Dimension b	25 mm
Dimension D	50 mm
Dimension H	47 mm
Dimension L	32.5 mm
Dimension L1	86 mm
Dimension t	3 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	50
Suitable in fire protection area	no
Size	M50
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10
Material thickness	3 mm
Nominal diameter	50 mm
UV-resistant	yes