


Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014005

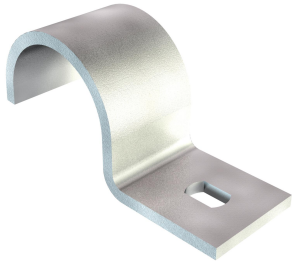

Fastening clip, single-lobe, 6 mm



St

Steel

FT

Hot-dip galvanised

Master data

Item number	1014005
Type	822 6 FT
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	6mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.885 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0225 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014005



Dimensions

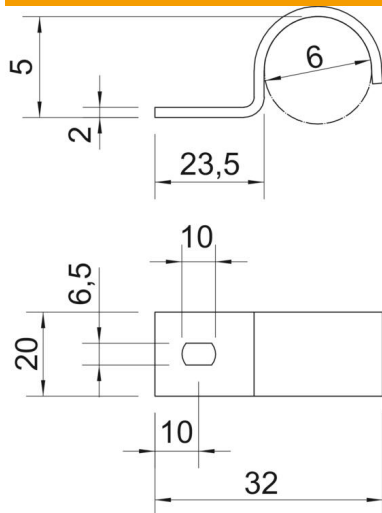

Length	32 mm
Width	20 mm
Height	5 mm
Dimension A	10 mm
Dimension b	20 mm
Dimension D	6 mm
Dimension H	5 mm
Dimension L	23.5 mm
Dimension L1	32 mm
Dimension t	2 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	6
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10
Material thickness	2 mm
Nominal diameter	6 mm
ROHS-conformant	yes
UV-resistant	yes