

Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014161



Fastening clip, single-lobe, 23 mm



St	Steel
FT	Hot-dip galvanised

Master data

Item number	1014161
Type	822 22.5 FT
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	23mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	50
Unit of quantity	Piece
Weight	2.338 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0459 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014161



Dimensions

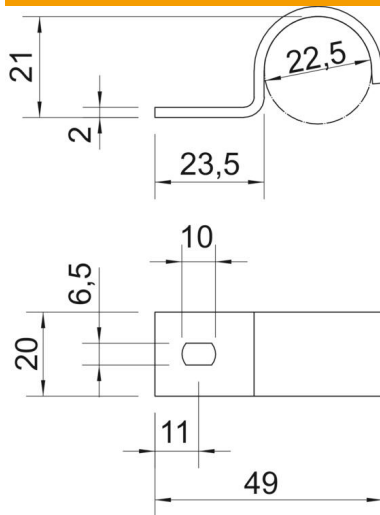

Length	49 mm
Width	20 mm
Height	21 mm
Dimension A	11 mm
Dimension b	20 mm
Dimension D	22.5 mm
Dimension H	21 mm
Dimension L	23.5 mm
Dimension L1	49 mm
Dimension t	2 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	22,5
Suitable in fire protection area	no
Size	PG16
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10
Material thickness	2 mm
Nominal diameter	22.5 mm
UV-resistant	yes