

Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014218



Fastening clip, single-lobe, 28 mm



St Steel

FT Hot-dip galvanised

Master data

Item number	1014218
Type	822 28.3 FT
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	28mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	50
Unit of quantity	Piece
Weight	4.42 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0889 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014218



Dimensions

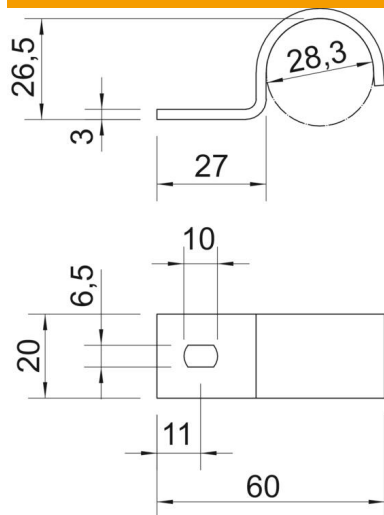

Length	60 mm
Width	20 mm
Height	26.5 mm
Dimension A	11 mm
Dimension b	20 mm
Dimension D	28.3 mm
Dimension H	26.5 mm
Dimension L	27 mm
Dimension L1	60 mm
Dimension t	3 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	28,3
Suitable in fire protection area	no
Size	PG21
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10
Material thickness	2 mm
Nominal diameter	28.3 mm
UV-resistant	yes