

# Technical data sheet

## Fastening clip 822, heavy duty, FT

Item number: 1014501



Fastening clip, single-lobe, 25 mm



|    |                    |
|----|--------------------|
| St | Steel              |
| FT | Hot-dip galvanised |

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 1014501                  |
| Type                               | 822 25 FT                |
| Description 1                      | Fastening clip           |
| Description 2                      | single lobe              |
| Manufacturer                       | OBO                      |
| Dimension                          | 25mm                     |
| Material                           | Steel                    |
| Surface                            | Hot-dip galvanised       |
| Surface standard                   | DIN EN ISO 1461          |
| Smallest sales unit                | 50                       |
| Unit of quantity                   | Piece                    |
| Weight                             | 2.4 kg                   |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0735 kg CO2e / 1 Piece |


# Technical data sheet

## Fastening clip 822, heavy duty, FT

Item number: 1014501



### Dimensions

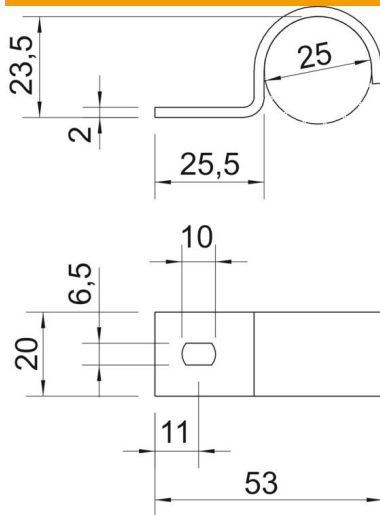

|              |         |
|--------------|---------|
| Length       | 53 mm   |
| Width        | 20 mm   |
| Height       | 23.5 mm |
| Dimension A  | 11 mm   |
| Dimension b  | 20 mm   |
| Dimension D  | 25 mm   |
| Dimension H  | 23.5 mm |
| Dimension L  | 25.5 mm |
| Dimension L1 | 53 mm   |
| Dimension t  | 3 mm    |

### Technical data

|                                  |             |
|----------------------------------|-------------|
| Distance to the wall             | no          |
| Number of cables/pipes           | 1           |
| Version for                      | Single-lobe |
| Fastening type                   | Screw hole  |
| For diameter                     | 25          |
| Suitable in fire protection area | no          |
| Size                             | M25         |
| Halogen-free                     | yes         |
| Plastic-covered                  | no          |
| Hole size                        | 6,5 x 10    |
| Material thickness               | 2 mm        |
| Nominal diameter                 | 25 mm       |
| UV-resistant                     | yes         |