

Technical data sheet

Fastening clip 822 V2A

Item number: 1014714



Single-lobe fastening clip for cables and pipes.



A2	Stainless steel
2B	Bright, treated

Master data	
Item number	1014714
Type	822 12 A2
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	12mm
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.45 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0793 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 822 V2A

Item number: 1014714



Dimensions

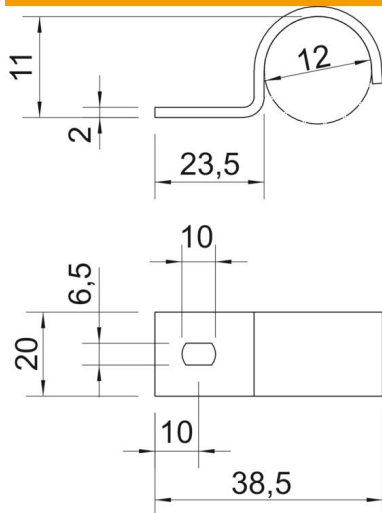

Dimension A	10 mm
Dimension b	20 mm
Dimension D	12 mm
Dimension H	11 mm
Dimension L	23.5 mm
Dimension L1	37.58 mm
Dimension t	2 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	12
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10
Material thickness	2 mm
Nominal diameter	12 mm
UV-resistant	yes