

Technical data sheet

Fastening clip 823, heavy duty

Item number: 1015494



Fastening clip, double-lobe, 25 mm



St Steel

FT Hot-dip galvanised

Master data

Item number	1015494
Type	823 25 FT
Description 1	Fastening clip
Description 2	two lobe
Manufacturer	OBO
Dimension	25mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	25
Unit of quantity	Piece
Weight	6.77 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1428 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 823, heavy duty

Item number: 1015494



Dimensions

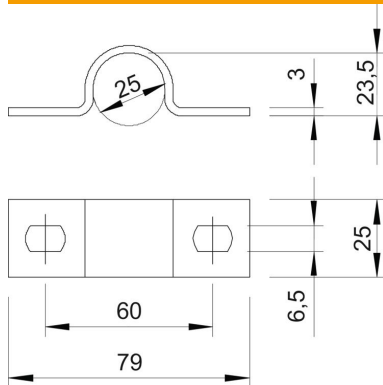

Length	79 mm
Width	25 mm
Height	23.5 mm
Dimension A	79 mm
Dimension B	60 mm
Dimension b	25 mm
Dimension D	25 mm
Dimension d	6.5 mm
Dimension e	10 mm
Dimension H	23.5 mm
Dimension t	3 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Screw hole
For diameter	25
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10
Material thickness	3 mm
Nominal diameter	25 mm
UV-resistant	yes