

Technical data sheet

Fastening clip 605, medium duty, aluminium

Item number: 1017926



Fastening clip, double-lobe, 32 mm



Alu Aluminium

Master data

Item number	1017926
Type	605 32 ALU
Description 1	Fastening clip
Description 2	two lobe
Manufacturer	OBO
Dimension	32mm
Material	Aluminium
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.433 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0724 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 605, medium duty, aluminium

Item number: 1017926



Dimensions

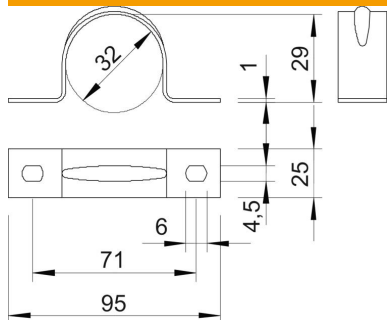

Length	95 mm
Width	25 mm
Height	29 mm
Dimension A	95 mm
Dimension B	71 mm
Dimension b	25 mm
Dimension D	32 mm
Dimension d	4.5 mm
Dimension e	6 mm
Dimension H	29 mm
Dimension t	1 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Screw hole
For diameter	32
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	4,5 x 6
Material thickness	1 mm
Nominal diameter	32 mm
ROHS-conformant	yes
Clamping range D, max.	32 mm
Clamping range D, min.	32 mm
UV-resistant	yes