

Technical data sheet

Fastening clip 605, medium duty, aluminium

Item number: 1017997



Fastening clip, double-lobe, 63 mm



Alu Aluminium

Master data

Item number	1017997
Type	605 63 ALU
Description 1	Fastening clip
Description 2	two lobe
Manufacturer	OBO
Dimension	63mm
Material	Aluminium
Smallest sales unit	25
Unit of quantity	Piece
Weight	1.26 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1816 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 605, medium duty, aluminium

Item number: 1017997



Dimensions

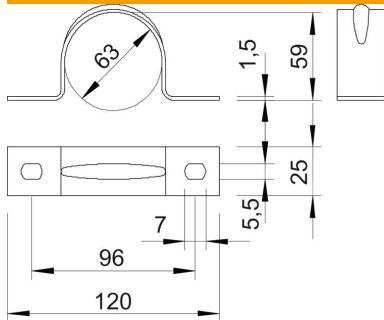

Length	120 mm
Width	25 mm
Height	59 mm
Dimension A	120 mm
Dimension B	96 mm
Dimension b	25 mm
Dimension D	63 mm
Dimension d	5.5 mm
Dimension e	7 mm
Dimension H	59 mm
Dimension t	1.5 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Screw hole
For diameter	63
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	5,5 x 7
Material thickness	1.5 mm
Nominal diameter	63 mm
Clamping range D, max.	63 mm
Clamping range D, min.	63 mm
UV-resistant	yes