

Technical data sheet

Fastening clip 605, medium duty, V4A

Item number: 1018693



Two lobe fastening clips for cables and pipes.



A4	Stainless steel
2B	Bright, treated

Master data

Item number	1018693
Type	605 32 A4
Description 1	Fastening clip
Description 2	two lobe
Manufacturer	OBO
Dimension	32mm
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.26 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0786 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 605, medium duty, V4A

Item number: 1018693



Dimensions

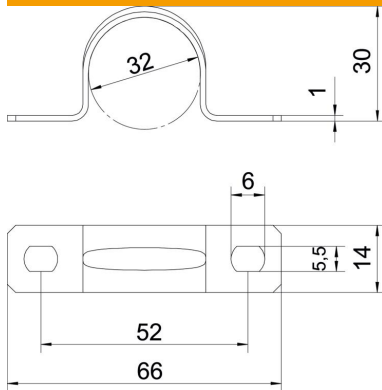

Length	66 mm
Width	14 mm
Height	30 mm
Dimension A	66 mm
Dimension B	52 mm
Dimension b	14 mm
Dimension D	32 mm
Dimension d	4.5 mm
Dimension e	6 mm
Dimension H	30 mm
Dimension t	1 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Screw hole
For diameter	32
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	4,5 x 6
Material thickness	1 mm
Nominal diameter	32 mm
UV-resistant	yes