

Technical data sheet

Fastening clip 605, medium duty, V4A

Item number: 1018705



Two lobe fastening clips for cables and pipes.



A4	Stainless steel
2B	Bright, treated

Master data

Item number	1018705
Type	605 40 A4
Description 1	Fastening clip
Description 2	two lobe
Manufacturer	OBO
Dimension	40mm
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	1.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1382 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 605, medium duty, V4A

Item number: 1018705



Dimensions

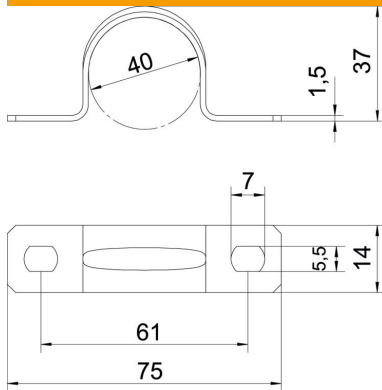

Length	75 mm
Width	14 mm
Height	37 mm
Dimension A	75 mm
Dimension B	61 mm
Dimension b	14 mm
Dimension D	40 mm
Dimension d	5.5 mm
Dimension e	7 mm
Dimension H	37 mm
Dimension t	1.5 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Screw hole
For diameter	40
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	5,5 x 7
Material thickness	1.5 mm
Nominal diameter	40 mm
UV-resistant	yes