


Technical data sheet

Fastening clip, plant standard 7855, double-lobe

Item number: 1044044

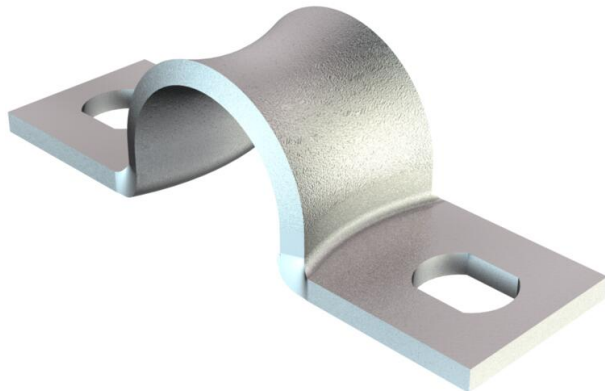

Dimensions to Siemens standard SN 78550, shape B, with strongly rounded edges, thus particularly suitable for sensitive cables.
* Sizes 3 to 10 not suitable for nail device.



St

Steel

GTP

Electrogalvanised, transparently-passivated

Master data

Item number	1044044
Type	WN 7855 B 3
Description 1	Fastening clip
Description 2	two lobe
Manufacturer	OBO
Dimension	3mm
Material	Steel
Surface	Electrogalvanised, transparently-passivated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.08 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0021 kg CO2e / 1 Piece


Technical data sheet

Fastening clip, plant standard 7855, double-lobe

Item number: 1044044



Dimensions

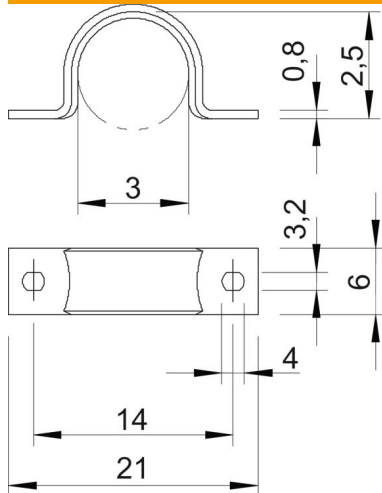

Length	21 mm
Width	6 mm
Height	2.5 mm
Dimension A	21 mm
Dimension B	14 mm
Dimension b	6 mm
Dimension D	3 mm
Dimension d	3.2 mm
Dimension e	4 mm
Dimension H	2.5 mm
Dimension L	21 mm
Dimension t	0.8 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Screw hole
For diameter	3
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	3,2 x 4
Material thickness	0.8 mm
Nominal diameter	3 mm
ROHS-conformant	yes
UV-resistant	yes