


# Technical data sheet

## Fastening clip, plant standard 7855, double-lobe

Item number: 1044192

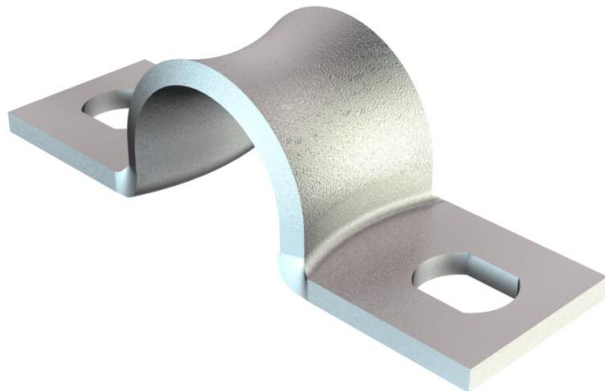

Dimensions to Siemens standard SN 78550, shape B, with strongly rounded edges, thus particularly suitable for sensitive cables.  
\* Sizes 3 to 10 not suitable for nail device.



Steel



Electrogalvanised, transparently-passivated

### Master data

|                                    |                                             |
|------------------------------------|---------------------------------------------|
| Item number                        | 1044192                                     |
| Type                               | WN 7855 B 10                                |
| Description 1                      | Fastening clip                              |
| Description 2                      | two lobe                                    |
| Manufacturer                       | OBO                                         |
| Dimension                          | 10mm                                        |
| Material                           | Steel                                       |
| Surface                            | Electrogalvanised, transparently-passivated |
| Surface standard                   |                                             |
| Smallest sales unit                | 100                                         |
| Unit of quantity                   | Piece                                       |
| Weight                             | 0.223 kg                                    |
| Weight unit                        | kg/100 pc.                                  |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0054 kg CO2e / 1 Piece                    |


# Technical data sheet

## Fastening clip, plant standard 7855, double-lobe

Item number: 1044192



### Dimensions

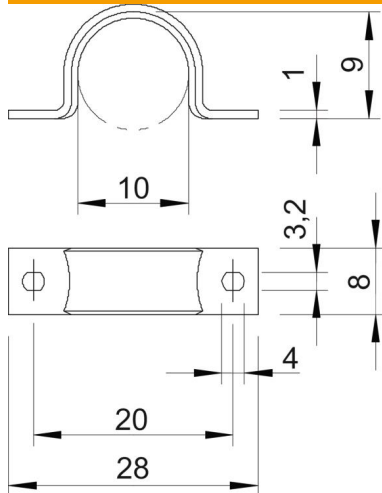

|             |        |
|-------------|--------|
| Length      | 28 mm  |
| Width       | 8 mm   |
| Height      | 9 mm   |
| Dimension A | 28 mm  |
| Dimension B | 20 mm  |
| Dimension b | 8 mm   |
| Dimension D | 10 mm  |
| Dimension d | 3.2 mm |
| Dimension e | 4 mm   |
| Dimension H | 9 mm   |
| Dimension L | 28 mm  |
| Dimension t | 1 mm   |

### Technical data

|                                  |            |
|----------------------------------|------------|
| Distance to the wall             | no         |
| Number of cables/pipes           | 1          |
| Version for                      | Two-lobe   |
| Fastening type                   | Screw hole |
| For diameter                     | 10         |
| Suitable in fire protection area | no         |
| Halogen-free                     | yes        |
| Plastic-covered                  | no         |
| Hole size                        | 3,2 x 4    |
| Material thickness               | 1.5 mm     |
| Nominal diameter                 | 10 mm      |
| UV-resistant                     | yes        |