


Technical data sheet

Fastening clip, plant standard 7855, double-lobe

Item number: 1044230

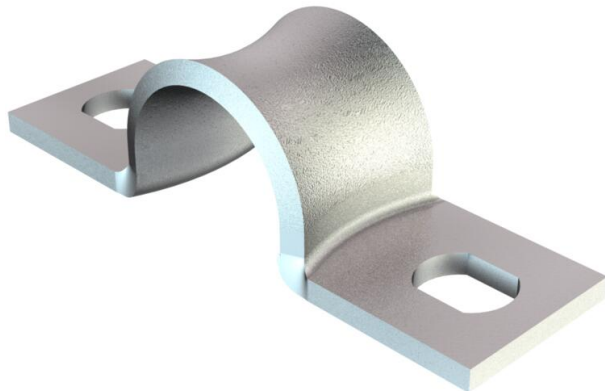

Dimensions to Siemens standard SN 78550, shape B, with strongly rounded edges, thus particularly suitable for sensitive cables.
* Sizes 3 to 10 not suitable for nail device.



St

Steel

GTP

Electrogalvanised, transparently-passivated

Master data

Item number	1044230
Type	WN 7855 B 14
Description 1	Fastening clip
Description 2	two lobe
Manufacturer	OBO
Dimension	14mm
Material	Steel
Surface	Electrogalvanised, transparently-passivated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.733 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0159 kg CO2e / 1 Piece


Technical data sheet

Fastening clip, plant standard 7855, double-lobe

Item number: 1044230



Dimensions

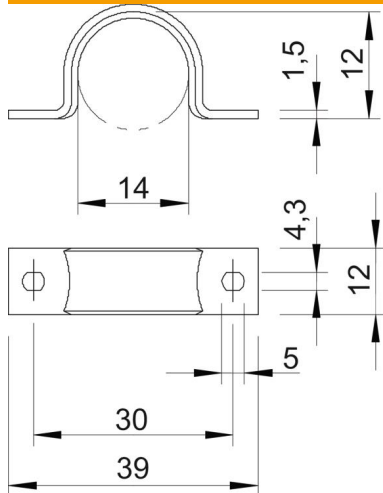

Length	39 mm
Width	12 mm
Height	12 mm
Dimension A	39 mm
Dimension B	30 mm
Dimension b	12 mm
Dimension D	14 mm
Dimension d	4.3 mm
Dimension e	5 mm
Dimension H	12 mm
Dimension L	39 mm
Dimension t	1.5 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Screw hole
For diameter	14
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	4,3 x 5
Material thickness	1.5 mm
Nominal diameter	14 mm
UV-resistant	yes