

# Technical data sheet

## CMS3518 profile rail, slot 17 mm, FS, perforated

Item number: 1104422



Central C profile rail for cable routing, in conjunction with clamp clips with a hammerhead foot. Can also be used as suspension construction for cable support systems.



|    |                  |
|----|------------------|
| St | Steel            |
| FS | Strip galvanised |

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 1104422                  |
| Type                               | CMS3518P0700FS           |
| Description 1                      | Profile rail             |
| Description 2                      | perforated, slot 17mm    |
| Manufacturer                       | OBO                      |
| Dimension                          | 700x35x18                |
| Material                           | Steel                    |
| Surface                            | Strip galvanised         |
| Surface standard                   | DIN EN 10346             |
| Smallest sales unit                | 10                       |
| Unit of quantity                   | Piece                    |
| Weight                             | 68.46 kg                 |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,6957 kg CO2e / 1 Piece |


# Technical data sheet

CMS3518 profile rail, slot 17 mm, FS, perforated

Item number: 1104422



## Dimensions

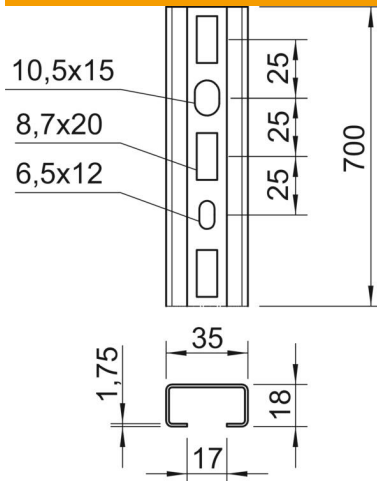

|             |        |
|-------------|--------|
| Length      | 700 mm |
| Width       | 35 mm  |
| Height      | 18 mm  |
| Dimension L | 700 mm |

## Technical data

|                               |                      |
|-------------------------------|----------------------|
| Breakable                     | no                   |
| Type of perforation           | Perforated back      |
| Version for                   | Single profile       |
| Drill hole spacing, centre    | 25 mm                |
| Maintain electrical functions | yes                  |
| Material thickness            | 1.75 mm              |
| With perforation              | yes                  |
| With toothing                 | no                   |
| Profile shape                 | C profile            |
| Rustproof steel, pickled      | no                   |
| Slot width                    | 17 mm                |
| Static value A                | 1.17 cm <sup>2</sup> |
| Static value I <sub>y</sub>   | 0.52 cm <sup>4</sup> |
| Static value I <sub>z</sub>   | 0.53 cm <sup>4</sup> |
| Static value W <sub>y</sub>   | 2.33 cm <sup>3</sup> |
| Static value W <sub>z</sub>   | 1.33 cm <sup>3</sup> |