

# Technical data sheet

## CML3518 profile rail, slot 17 mm, FT, perforated

Item number: 1104556



Central C profile rail for cable routing, in conjunction with clamp clips with a hammerhead foot. Can also be used as suspension construction for cable support systems.



|    |                    |
|----|--------------------|
| St | Steel              |
| FT | Hot-dip galvanised |

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 1104556                  |
| Type                               | CML3518P0400FT           |
| Description 1                      | Profile rail             |
| Description 2                      | perforated, slot 17mm    |
| Manufacturer                       | OBO                      |
| Dimension                          | 400x35x18                |
| Material                           | Steel                    |
| Surface                            | Hot-dip galvanised       |
| Surface standard                   | DIN EN ISO 1461          |
| Smallest sales unit                | 10                       |
| Unit of quantity                   | Piece                    |
| Weight                             | 30.5 kg                  |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,6933 kg CO2e / 1 Piece |


# Technical data sheet

CML3518 profile rail, slot 17 mm, FT, perforated

Item number: 1104556



## Dimensions

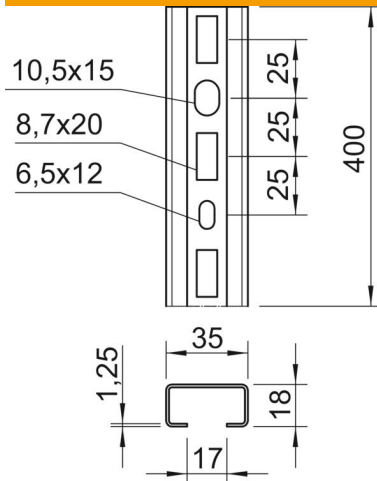

|             |        |
|-------------|--------|
| Length      | 400 mm |
| Width       | 35 mm  |
| Height      | 18 mm  |
| Dimension L | 400 mm |

## Technical data

|                               |                      |
|-------------------------------|----------------------|
| Breakable                     | no                   |
| Type of perforation           | Perforated back      |
| Version for                   | Single profile       |
| Maintain electrical functions | yes                  |
| Material thickness            | 1.25 mm              |
| With perforation              | yes                  |
| With tothing                  | no                   |
| Profile shape                 | C profile            |
| Rustproof steel, pickled      | no                   |
| Slot width                    | 17 mm                |
| Static value A                | 0.88 cm <sup>2</sup> |
| Static value I <sub>y</sub>   | 0.41 cm <sup>4</sup> |
| Static value I <sub>z</sub>   | 1.81 cm <sup>4</sup> |
| Static value W <sub>y</sub>   | 0.41 cm <sup>3</sup> |
| Static value W <sub>z</sub>   | 1.03 cm <sup>3</sup> |