

Technical data sheet

CL2008 profile rail, slot 11 mm, A2, unperforated

Item number: 1105125



Light-duty C profile rail for cable routing, in conjunction with series clips or clamp clips with N foot. Can also be used in building of control cabinets.



A2 Stainless steel

2B Bright, treated

Master data

Item number	1105125
Type	CL2008UP2000A2
Description 1	Profile rail
Description 2	unperforated, slot 11mm
Manufacturer	OBO
Dimension	2000x20x8
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	2
Unit of quantity	Metre
Weight	23.55 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,2039 kg CO2e / 1 Meter


Technical data sheet

CL2008 profile rail, slot 11 mm, A2, unperforated

Item number: 1105125



Dimensions

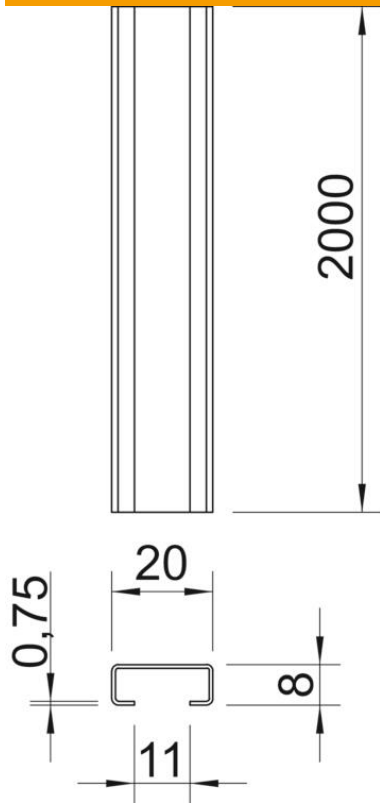

Length	2,000 mm
Width	20 mm
Height	8 mm
Dimension L	2,000 mm

Technical data

Breakable	no
Type of perforation	Without
Version for	Single profile
Drill hole spacing, centre	10 mm
Bundle	20 m
Maintain electrical functions	no
Material thickness	0.75 mm
With perforation	no
With toothing	no
Profile shape	C profile
Slot width	11 mm
Static value A	0.3 cm ²
Static value I _y	0.03 cm ⁴
Static value I _z	0.17 cm ⁴
Static value W _y	0.03 cm ³
Static value W _z	0.17 cm ³