


Technical data sheet

Profile rail CL2712, slot 12 mm, BK, unperforated

Item number: 1109014

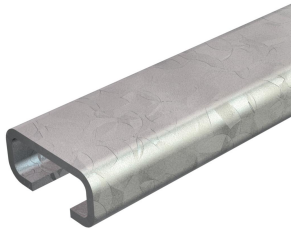

Light-duty C profile rail for cable routing, in conjunction with series clips or clamp clips with N foot. Can also be used in building of control cabinets.



St Steel

BK Bright

Master data

Item number	1109014
Type	CL2712UP2000BK
Description 1	Profile rail
Description 2	unperforated, slot 12mm
Manufacturer	OBO
Dimension	2000x27x12,5
Material	Steel
Surface	Bright
Surface standard	
Smallest sales unit	2
Unit of quantity	Metre
Weight	90 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,5815 kg CO2e / 1 Meter


Technical data sheet

Profile rail CL2712, slot 12 mm, BK, unperforated

Item number: 1109014



Dimensions

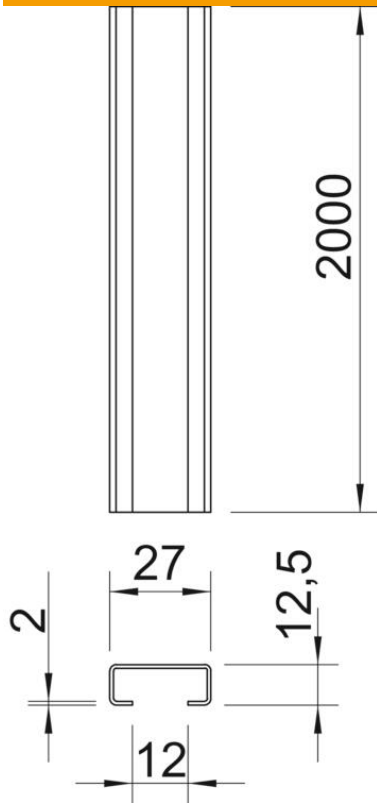

Length	2,000 mm
Width	27 mm
Height	12.5 mm
Dimension L	2,000 mm

Technical data

Breakable	no
Type of perforation	Without
Version for	Single profile
Bundle	20 m
Maintain electrical functions	no
Material thickness	2 mm
With perforation	no
With tothing	no
Profile shape	C profile
Static value A	1.08 cm ²
Static value Iz	0.98 cm ⁴