


# Technical data sheet

Profile rail CL2712, slot 12 mm, FT, unperforated

Item number: 1109022

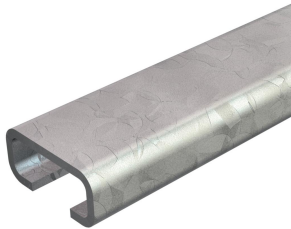

Light-duty C profile rail for cable routing, in conjunction with series clips or clamp clips with N foot. Can also be used in building of control cabinets.



|    |                    |
|----|--------------------|
| St | Steel              |
| FT | Hot-dip galvanised |

## Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 1109022                  |
| Type                               | CL2712UP2000FT           |
| Description 1                      | Profile rail             |
| Description 2                      | unperforated, slot 12mm  |
| Manufacturer                       | OBO                      |
| Dimension                          | 2000x27x12,5             |
| Material                           | Steel                    |
| Surface                            | Hot-dip galvanised       |
| Surface standard                   | DIN EN ISO 1461          |
| Smallest sales unit                | 2                        |
| Unit of quantity                   | Metre                    |
| Weight                             | 90 kg                    |
| Weight unit                        | kg/100 m                 |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,8227 kg CO2e / 1 Meter |


# Technical data sheet

Profile rail CL2712, slot 12 mm, FT, unperforated

Item number: 1109022



## Dimensions

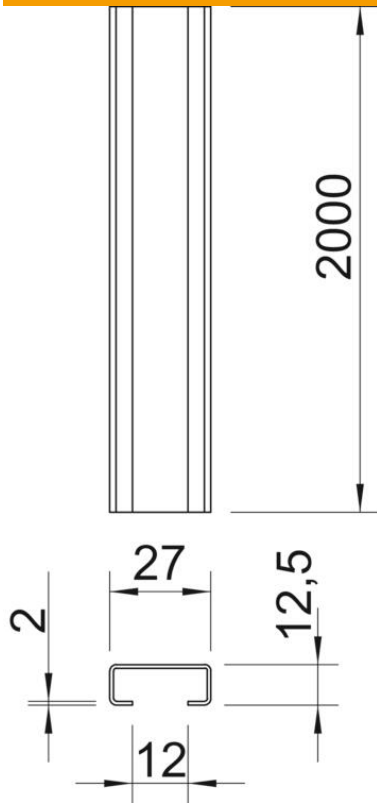

|             |          |
|-------------|----------|
| Length      | 2,000 mm |
| Width       | 27 mm    |
| Height      | 12.5 mm  |
| Dimension L | 2,000 mm |

## Technical data

|                               |                      |
|-------------------------------|----------------------|
| Breakable                     | no                   |
| Type of perforation           | Without              |
| Version for                   | Single profile       |
| Bundle                        | 20 m                 |
| Maintain electrical functions | no                   |
| Material thickness            | 2 mm                 |
| With perforation              | no                   |
| With tothing                  | no                   |
| Profile shape                 | C profile            |
| Slot width                    | 12 mm                |
| Static value A                | 1.08 cm <sup>2</sup> |
| Static value Iz               | 0.98 cm <sup>4</sup> |