

Technical data sheet

CL2712 profile rail, slot 12 mm, FT, perforated

Item number: 1109529



Light-duty C profile rail for cable routing, in conjunction with series clips or clamp clips with N foot. Can also be used in building of control cabinets.



St Steel

FT Hot-dip galvanised

Master data

Item number	1109529
Type	CL2712P2000FT
Description 1	Profile rail
Description 2	perforated, slot 12mm
Manufacturer	OBO
Dimension	2000x27x12,5
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	2
Unit of quantity	Metre
Weight	89.5 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,9454 kg CO2e / 1 Meter


Technical data sheet

CL2712 profile rail, slot 12 mm, FT, perforated

Item number: 1109529



Dimensions

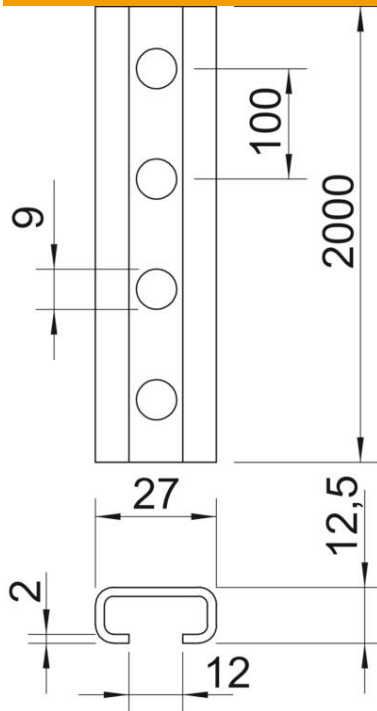

Length	2,000 mm
Width	27 mm
Height	12.5 mm
Dimension L	2,000 mm

Technical data

Breakable	no
Type of perforation	Perforated back
Version for	Single profile
Drill hole spacing, centre	100 mm
Bundle	20 m
Maintain electrical functions	no
Material thickness	2 mm
With perforation	yes
With tothing	no
Profile shape	C profile
Slot width	12 mm
Static value A	0.89 cm ²
Static value I _y	0.17 cm ⁴
Static value I _z	0.98 cm ⁴
Static value W _y	0.25 cm ³
Static value W _z	0.72 cm ³