

Technical data sheet

CL3015 profile rail, 16 mm slot, FT, perforated

Item number: 1109863



Profile rail, perforated, slot width 16 mm.



- St

Steel
- FT

Hot-dip galvanised

Master data		
Item number	1109863	
Type	CM3015P1000FT	
Description 1	Profile rail	
Description 2	perforated, slot 16mm	
Manufacturer	OBO	
Dimension	1000x30x15	
Material	Steel	
Surface	Hot-dip galvanised	
Surface standard	DIN EN ISO 1461	
Smallest sales unit	10	
Unit of quantity	Metre	
Weight	73 kg	
Weight unit	kg/100 m	
CO2 Footprint (GWP) Cradle-to-Gate	1,661 kg CO2e / 1 Meter	


Technical data sheet

CL3015 profile rail, 16 mm slot, FT, perforated

Item number: 1109863



Dimensions

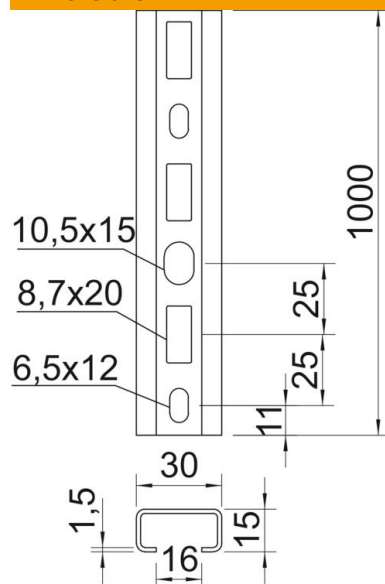

Length	1,000 mm
Width	30 mm
Height	15 mm
Dimension L	1,000 mm

Technical data

Breakable	no
Type of perforation	Perforated back
Version for	Single profile
Drill hole spacing, centre	25 mm
Bundle	10 m
Maintain electrical functions	no
Material thickness	1.5 mm
With perforation	yes
With toothing	no
Profile shape	C profile
Slot width	16 mm
Static value A	0.8 cm ²
Static value I _y	0.24 cm ⁴
Static value I _z	1.22 cm ⁴
Static value W _y	0.29 cm ³
Static value W _z	0.81 cm ³