

Technical data sheet

CL3015 profile rail, 16 mm slot, FT, perforated

Item number: 1109871



Profile rail, perforated, slot width 16 mm.



- St

Steel
- FT

Hot-dip galvanised

Master data	
Item number	1109871
Type	CM3015P2000FT
Description 1	Profile rail
Description 2	perforated, slot 16mm
Manufacturer	OBO
Dimension	2000x30x15
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	2
Unit of quantity	Metre
Weight	73 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,6414 kg CO2e / 1 Meter


Technical data sheet

CL3015 profile rail, 16 mm slot, FT, perforated

Item number: 1109871



Dimensions

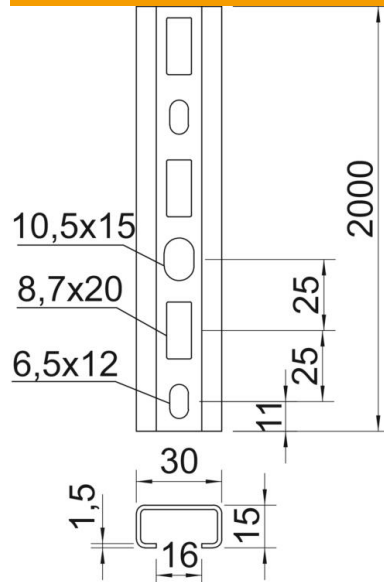

Length	2,000 mm
Width	30 mm
Height	15 mm
Dimension L	2,000 mm

Technical data

Breakable	no
Type of perforation	Perforated back
Version for	Single profile
Drill hole spacing, centre	25 mm
Bundle	20 m
Maintain electrical functions	no
Material thickness	1.5 mm
With perforation	yes
With toothing	no
Profile shape	C profile
Slot width	16 mm
Static value A	0.8 cm ²
Static value I _y	0.24 cm ⁴
Static value I _z	1.22 cm ⁴
Static value W _y	0.29 cm ³
Static value W _z	0.81 cm ³