


Technical data sheet

CM3015 profile rail, slot 16 mm, FS, unperforated

Item number: 1110004

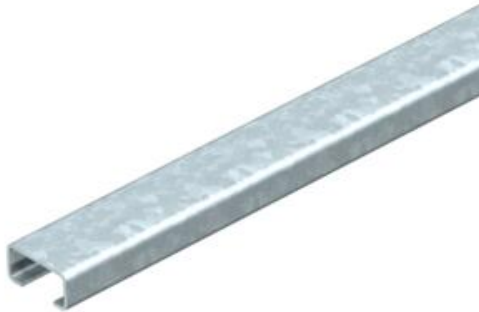

Profile rail, unperforated, slot width 16 mm, 2,000 x 30 x 15



St	Steel
FS	Strip galvanised

Master data

Item number	1110004
Type	CM3015UP2000FS
Description 1	Profile rail
Description 2	unperforated, slot 16mm
Manufacturer	OBO
Dimension	2000x30x15
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	2
Unit of quantity	Metre
Weight	75.5 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,7112 kg CO2e / 1 Meter


Technical data sheet

CM3015 profile rail, slot 16 mm, FS, unperforated

Item number: 1110004



Dimensions

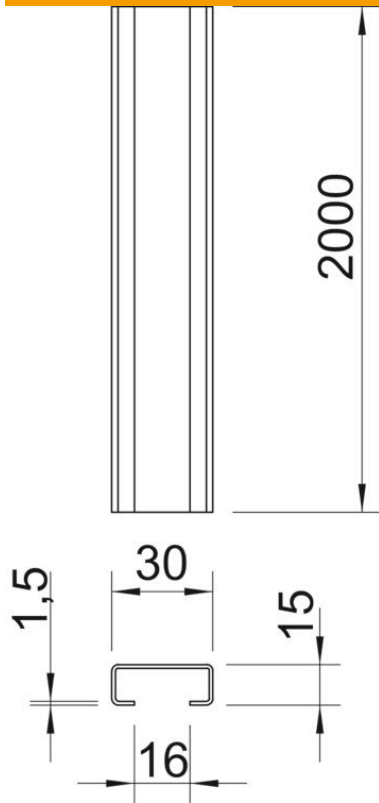

Length	2,000 mm
Width	30 mm
Height	15 mm
Dimension L	2,000 mm

Technical data

Breakable	no
Type of perforation	Without
Version for	Single profile
Maintain electrical functions	no
Material thickness	1.5 mm
With perforation	no
With toothing	no
Profile shape	C profile
Slot width	16 mm
Static value A	0.96 cm ²
Static value I _y	0.29 cm ⁴
Static value I _z	1.23 cm ⁴
Static value W _y	0.31 cm ³
Static value W _z	0.82 cm ³