


# Technical data sheet

## AMS3518 anchor rail, slot 16.5 mm, BK, unperforated

Item number: 1112074



Central C profile rail for cable routing, in conjunction with clamp clips with a hammerhead foot. Can also be used as suspension construction for cable support systems.

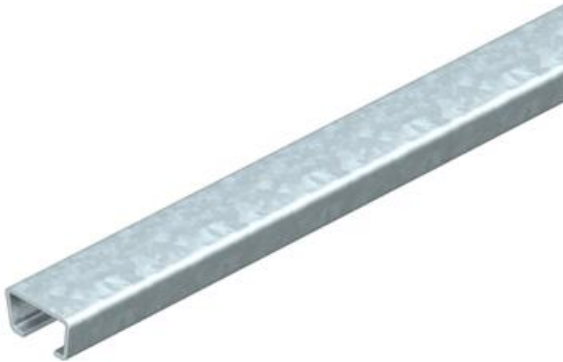

|           |        |
|-----------|--------|
| <b>St</b> | Steel  |
| <b>BK</b> | Bright |

### Master data

|                                    |                           |
|------------------------------------|---------------------------|
| Item number                        | 1112074                   |
| Type                               | AMS3518UP6000BK           |
| Description 1                      | Profile rail              |
| Description 2                      | unperforated, slot 16.5mm |
| Manufacturer                       | OBO                       |
| Dimension                          | 6000x35x18                |
| Material                           | Steel                     |
| Surface                            | Bright                    |
| Surface standard                   |                           |
| Smallest sales unit                | 6                         |
| Unit of quantity                   | Metre                     |
| Weight                             | 116 kg                    |
| Weight unit                        | kg/100 m                  |
| CO2 Footprint (GWP) Cradle-to-Gate | 2,1145 kg CO2e / 1 Meter  |


# Technical data sheet

AMS3518 anchor rail, slot 16.5 mm, BK, unperforated

Item number: 1112074



## Dimensions

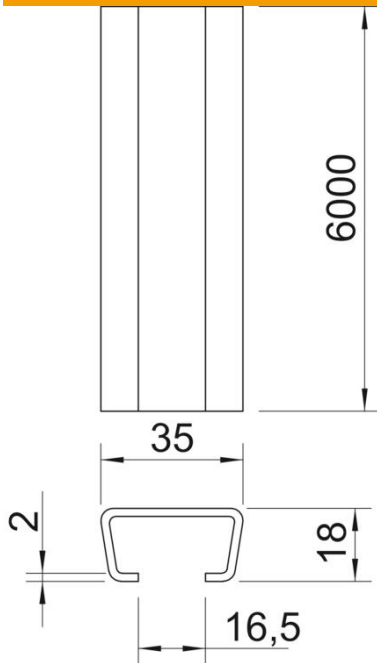

|             |          |
|-------------|----------|
| Length      | 6,000 mm |
| Width       | 35 mm    |
| Height      | 18 mm    |
| Dimension L | 6,000 mm |

## Technical data

|                               |                      |
|-------------------------------|----------------------|
| Breakable                     | no                   |
| Type of perforation           | Without              |
| Version for                   | Single profile       |
| Bundle                        | 6 m                  |
| Maintain electrical functions | no                   |
| Material thickness            | 2 mm                 |
| With perforation              | no                   |
| With tothing                  | no                   |
| Profile shape                 | C profile            |
| Slot width                    | 16.5 mm              |
| Static value A                | 1.48 cm <sup>2</sup> |
| Static value I <sub>y</sub>   | 0.6 cm <sup>4</sup>  |
| Static value I <sub>z</sub>   | 2.33 cm <sup>4</sup> |
| Static value W <sub>y</sub>   | 0.54 cm <sup>3</sup> |
| Static value W <sub>z</sub>   | 1.33 cm <sup>3</sup> |