


# Technical data sheet

## AMS3518 anchor rail, slot 16.5 mm, FT, unperforated

Item number: 1112228



Central C profile rail for cable routing, in conjunction with clamp clips with a hammerhead foot. Can also be used as suspension construction for cable support systems.

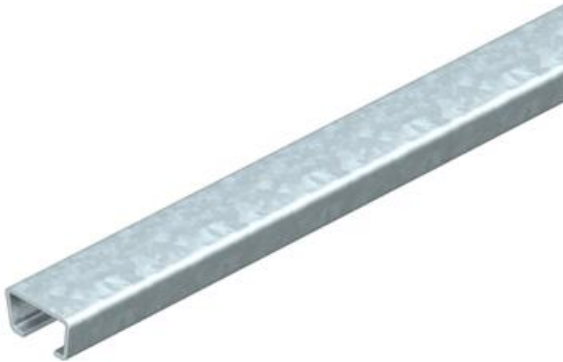

|    |                    |
|----|--------------------|
| St | Steel              |
| FT | Hot-dip galvanised |

### Master data

|                                    |                           |
|------------------------------------|---------------------------|
| Item number                        | 1112228                   |
| Type                               | AMS3518UP2000FT           |
| Description 1                      | Profile rail              |
| Description 2                      | unperforated, slot 16.5mm |
| Manufacturer                       | OBO                       |
| Dimension                          | 2000x35x18                |
| Material                           | Steel                     |
| Surface                            | Hot-dip galvanised        |
| Surface standard                   | DIN EN ISO 1461           |
| Smallest sales unit                | 2                         |
| Unit of quantity                   | Metre                     |
| Weight                             | 121.35 kg                 |
| Weight unit                        | kg/100 m                  |
| CO2 Footprint (GWP) Cradle-to-Gate | 2,4475 kg CO2e / 1 Meter  |


# Technical data sheet

AMS3518 anchor rail, slot 16.5 mm, FT, unperforated

Item number: 1112228



## Dimensions

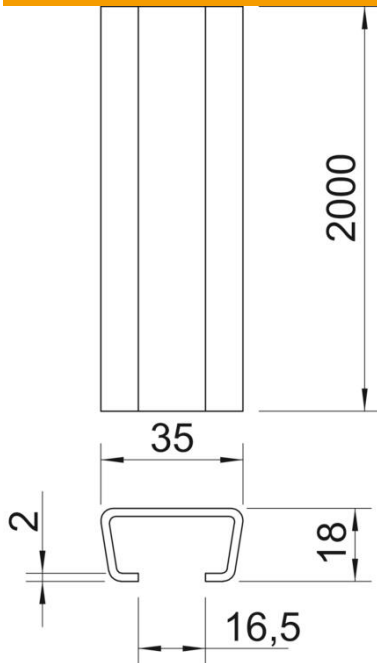

|             |          |
|-------------|----------|
| Length      | 2,000 mm |
| Width       | 35 mm    |
| Height      | 18 mm    |
| Dimension L | 2,000 mm |

## Technical data

|                               |                      |
|-------------------------------|----------------------|
| Breakable                     | no                   |
| Type of perforation           | Without              |
| Version for                   | Single profile       |
| Bundle                        | 20 m                 |
| Maintain electrical functions | no                   |
| Material thickness            | 2 mm                 |
| With perforation              | no                   |
| With tothing                  | no                   |
| Profile shape                 | C profile            |
| Slot width                    | 16.5 mm              |
| Static value A                | 1.48 cm <sup>2</sup> |
| Static value I <sub>y</sub>   | 0.6 cm <sup>4</sup>  |
| Static value I <sub>z</sub>   | 2.33 cm <sup>4</sup> |
| Static value W <sub>y</sub>   | 0.54 cm <sup>3</sup> |
| Static value W <sub>z</sub>   | 1.33 cm <sup>3</sup> |