

Technical data sheet

Hat profile rail unperforated GTP

Item number: 1115332



Hat profile rail 15 x 5 mm to DIN EN 60715 (formerly DIN EN 50045).



St Steel

GTP Electrogalvanised, transparently-passivated

Master data

Item number	1115332
Type	46277 GTP
Description 1	Top hat rail
Description 2	unperforated
Manufacturer	OBO
Dimension	2000x15x5
Material	Steel
Surface	Electrogalvanised, transparently-passivated
Surface standard	
Smallest sales unit	2
Unit of quantity	Metre
Weight	12.4 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,3044 kg CO2e / 1 Meter


Technical data sheet

Hat profile rail unperforated GTP


Item number: 1115332



Dimensions

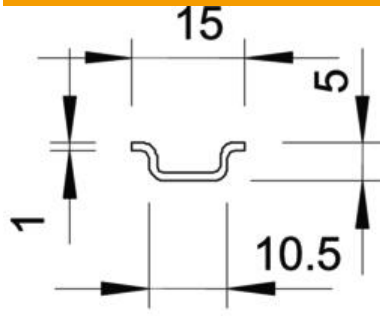

Length	2,000 mm
Width	15 mm
Height	5 mm

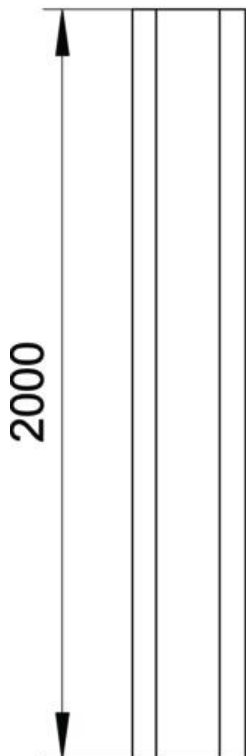

Technical data

Version for	Unperforated
Version, rails	Support rail DIN EN 60715
Bundle	50 m
Hole shape (ETIM)	Without
Material thickness	1 mm