

Technical data sheet

Hat profile rail, unperforated FS

Item number: 1115626



Hat profile rail 35 x 7.5 mm to DIN EN 60715 (formerly DIN EN 50022).



- StSteel
- FSStrip galvanised

Master data	
Item number	1115626
Type	2069 2M FS
Description 1	Top hat rail
Description 2	unperforated
Manufacturer	OBO
Dimension	2000x35x7,5
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	50
Unit of quantity	Metre
Weight	36.033 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,7825 kg CO2e / 1 Meter


Technical data sheet

Hat profile rail, unperforated FS


Item number: 1115626



Dimensions

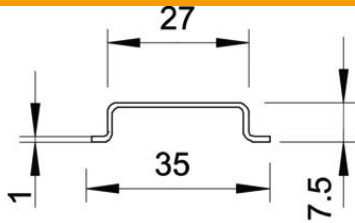

Length	2,000 mm
Width	35 mm
Height	7.5 mm

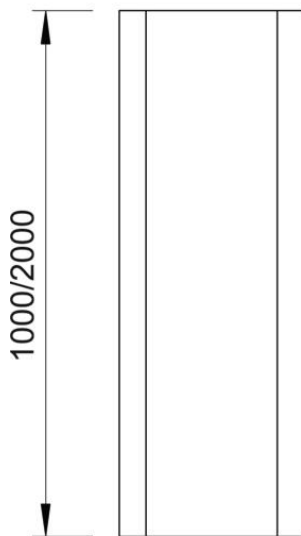

Technical data

Version for	Unperforated
Version, rails	Support rail DIN EN 60715
Bundle	50 m
Hole shape (ETIM)	Without
Material thickness	1 mm