

Technical data sheet

Hat profile rail, perforated FS

Item number: 1115804



Hat profile rail 35 x 7.5 mm to DIN EN 60715 (formerly DIN EN 50022).



St	Steel
FS	Strip galvanised

Master data

Item number	1115804
Type	2069 L 2M FS
Description 1	Top hat rail
Description 2	perforated
Manufacturer	OBO
Dimension	2000x35x7,5
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	2
Unit of quantity	Metre
Weight	33.28 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,7826 kg CO2e / 1 Meter


Technical data sheet

Hat profile rail, perforated FS

Item number: 1115804



Dimensions

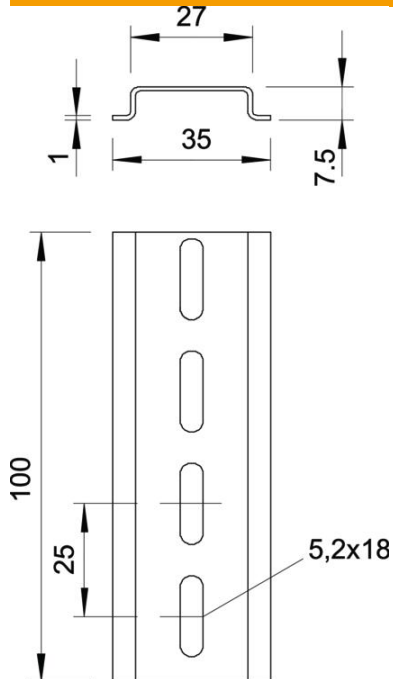

Length	2,000 mm
Width	35 mm
Height	7.5 mm

Technical data

Version for	Perforated
Version, rails	Support rail DIN EN 60715
Drill hole spacing, centre	25 mm
Bundle	50 m
Hole shape (ETIM)	Long slot
Material thickness	1 mm