

Technical data sheet

Hat profile rail, unperforated

Item number: 1115855



Hat profile rail 35 x 7.5 mm to DIN EN 60715 (formerly DIN EN 50022).



- St

Steel
- BK

Bright

Master data	
Item number	1115855
Type	2069 3M BK
Description 1	Top hat rail
Description 2	unperforated
Manufacturer	OBO
Dimension	3000x35x7,5
Material	Steel
Surface	Bright
Surface standard	
Smallest sales unit	3
Unit of quantity	Metre
Weight	36.034 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,6227 kg CO2e / 1 Meter


Technical data sheet

Hat profile rail, unperforated


Item number: 1115855



Dimensions

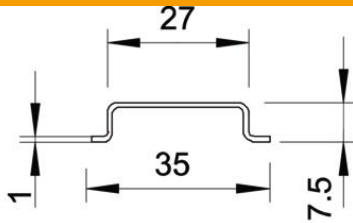

Length	3,000 mm
Width	35 mm
Height	7.5 mm

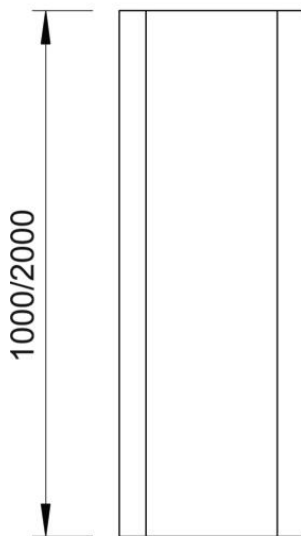

Technical data

Version for	Unperforated
Version, rails	Support rail DIN EN 60715
Hole shape (ETIM)	Without
Material thickness	1 mm