

Technical data sheet

CL2512 profile rail, 11 mm slot, FT, unperforated

Item number: 1117025



Light-duty C profile rail for cable routing, in conjunction with series clips or clamp clips with N foot. Can also be used in building of control cabinets.



St	Steel
FT	Hot-dip galvanised

Master data

Item number	1117025
Type	AL2512UP2000FT
Description 1	Profile rail
Description 2	unperforated, slot 11mm
Manufacturer	OBO
Dimension	2000x25x12
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	2
Unit of quantity	Metre
Weight	65 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,4087 kg CO2e / 1 Meter


Technical data sheet

CL2512 profile rail, 11 mm slot, FT, unperforated

Item number: 1117025



Dimensions

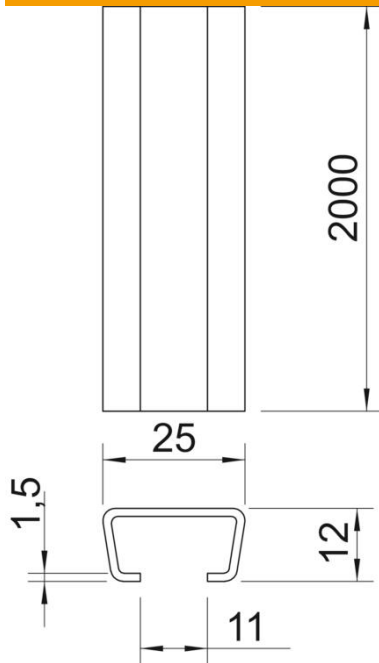

Length	2,000 mm
Width	25 mm
Height	12 mm
Dimension L	2,000 mm

Technical data

Type of perforation	Without
Version for	Single profile
Bundle	20 m
Material thickness	1.5 mm
With perforation	no
With tothing	no
Profile shape	C profile
Slot width	11 mm
Static value A	0.77 cm ²
Static value I _y	0.14 cm ⁴
Static value I _z	0.59 cm ⁴
Static value W _y	0.19 cm ³
Static value W _z	0.47 cm ³