

Technical data sheet

Profile rail CL2512, slot 11 mm, A2, unperforated

Item number: 1117068



Light-duty C profile rail for cable routing, in conjunction with series clips or clamp clips with N foot. Can also be used in building of control cabinets.



A2 Stainless steel

Master data

Item number	1117068
Type	AL2512UP2000A2
Description 1	Profile rail
Description 2	unperforated, slot 11mm
Manufacturer	OBO
Dimension	2000x25x12
Material	Stainless steel 1.4301
Smallest sales unit	2
Unit of quantity	Metre
Weight	58.3 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	2,807 kg CO2e / 1 Meter


Technical data sheet

Profile rail CL2512, slot 11 mm, A2, unperforated

Item number: 1117068



Dimensions

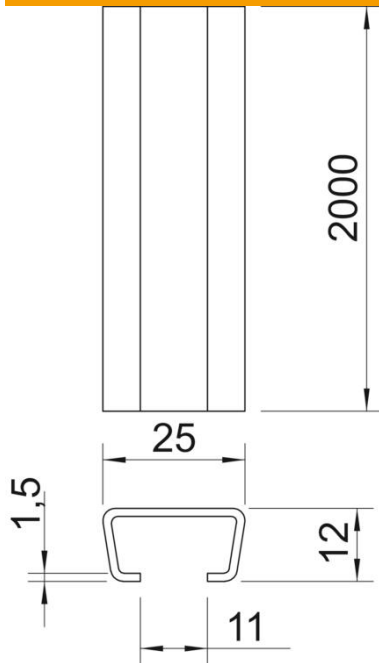

Length	2,000 mm
Width	25 mm
Height	12 mm
Dimension L	2,000 mm

Technical data

Type of perforation	Without
Version for	Single profile
Bundle	20 m
Material thickness	1.5 mm
With perforation	no
With tothing	no
Profile shape	C profile
Slot width	11 mm
Static value A	0.77 cm ²
Static value I _y	0.14 cm ⁴
Static value I _z	0.59 cm ⁴
Static value W _y	0.19 cm ³
Static value W _z	0.47 cm ³